


CC600-18-9S-1 Cut Sheet

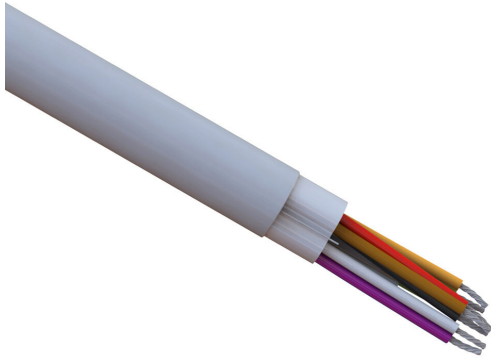

Quabbin control cable, shielded, 9 conductors, 18 AWG, 16-stranded, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CC600-18-9S-1>

Technical Specifications

Brand	Quabbin
Item	Cable
Wire/Cable Type	Control
UL Wire/Cable Type	AWM
Applicable Standards	UL 2586
Application	General purpose
Flexibility	Flexible
Voltage Rating	600V rated (UL)
Conductors	9 conductors
Conductor Size	18 AWG
Conductor Stranding	16-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	PVC
Conductor Insulation Color	Black, brown, red, orange, yellow, green, blue, violet and gray

Shielding	Shielded
Jacket Material	PVC
Jacket Color	Gray
Nominal Overall Cable Diameter	0.351in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 75ft = Coil• 76 to 315ft = 14 x 7in Reel• 316 to 450ft = 14 x 10in Reel• 451 to 695ft = 16 x 10in Reel• 696 to 970ft = 18 x 10in Reel• 971 to 1260ft = 18 x 13in Reel• 1261 to 2820ft = 24 x 17in Wooden Reel• 2821 to 4510ft = 30 x 17in Wooden Reel• 4511 to 5000ft = Large Wooden Reel

Agency Approvals

UL Listed File #	E69976
UL Recognized File #	None
UL Hazardous File #	None
CSA File #	LL51726
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement