


CC600-20-12U-1 Cut Sheet

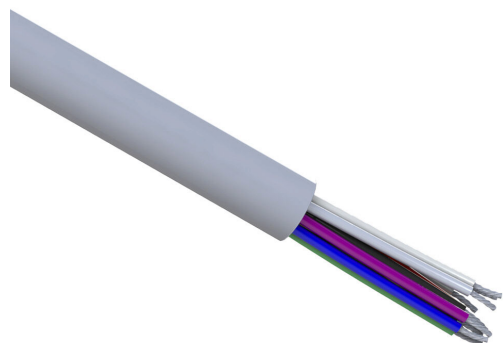

Quabbin flexible control cable, unshielded, 12 conductors, 20 AWG, 7-stranded, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CC600-20-12U-1>

Technical Specifications

Brand	Quabbin
Item	Cable
Wire/Cable Type	Control
UL Wire/Cable Type	AWM
Applicable Standards	UL 2586
Application	General purpose
Flexibility	Flexible
Voltage Rating	600V rated (UL)
Conductors	12 conductors
Conductor Size	20 AWG
Conductor Stranding	7-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	PVC
Conductor Insulation Color	Black, brown, red, orange, yellow, green, blue, violet, gray, white, white/black and white/brown

Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Gray
Nominal Overall Cable Diameter	0.351in
Bulk Length	Cut to length
Package Type	1 to 75ft = Coil, 76 to 315ft = 14 x 7in Reel, 316 to 450ft = 14 x 10in Reel, 451 to 695ft = 16 x 10in Reel, 696 to 970ft = 18 x 10in Reel, 971 to 1260ft = 18 x 13in Reel, 1261 to 2820ft = 24 x 17in Wooden Reel, 2821 to 4510ft = 30 x 17in Wooden Reel, 4511 to 10000ft = Large Wooden Reel

Agency Approvals

UL Listed File #	E69976
UL Recognized File #	None
UL Hazardous File #	None
CSA File #	LL51726
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement