


# CC600-20-12U-1 Cut Sheet

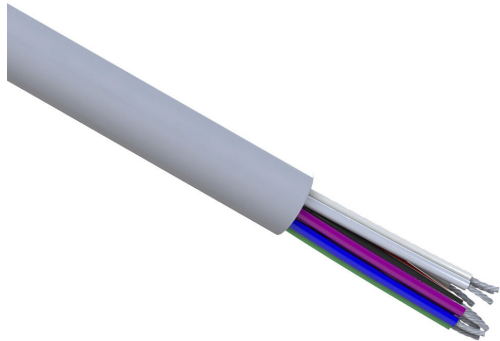

Quabbin flexible control cable, unshielded, 12 conductors, 20 AWG, 7-stranded, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CC600-20-12U-1>

## Technical Specifications

<b>Brand</b>	Quabbin	<b>Shielding</b>	Unshielded
<b>Item</b>	Cable	<b>Jacket Material</b>	PVC
<b>Wire/Cable Type</b>	Control	<b>Jacket Color</b>	Gray
<b>UL Wire/Cable Type</b>	AWM	<b>Nominal Overall Cable Diameter</b>	0.351in
<b>Applicable Standards</b>	UL 2586	<b>Bulk Length</b>	Cut to length
<b>Application</b>	General purpose	<b>Package Type</b>	<ul style="list-style-type: none"><li>• 20 to 75ft = Coil</li><li>• 76 to 315ft = 14 x 7in Reel</li><li>• 316 to 450ft = 14 x 10in Reel</li><li>• 451 to 695ft = 16 x 10in Reel</li><li>• 696 to 970ft = 18 x 10in Reel</li><li>• 971 to 1260ft = 18 x 13in Reel</li><li>• 1261 to 2820ft = 24 x 17in Wooden Reel</li><li>• 2821 to 4510ft = 30 x 17in Wooden Reel</li><li>• 4511 to 5000ft = Large Wooden Reel</li></ul>
<b>Flexibility</b>	Flexible		
<b>Voltage Rating</b>	600V rated (UL)		
<b>Conductors</b>	12 conductors		
<b>Conductor Size</b>	20 AWG		
<b>Conductor Stranding</b>	7-stranded		
<b>Conductor Material</b>	Tinned copper		
<b>Conductor Insulation Material</b>	PVC		
<b>Conductor Insulation Color</b>	Black, brown, red, orange, yellow, green, blue, violet, gray, white, white/black and white/brown		

## Agency Approvals

<b>UL Listed File #</b>	E69976
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CSA File #</b>	LL51726
<b>RoHS Status</b>	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>
<b>Other</b>	<a href="#">RoHS Statement</a>