


CC600-20-15U-1 Cut Sheet

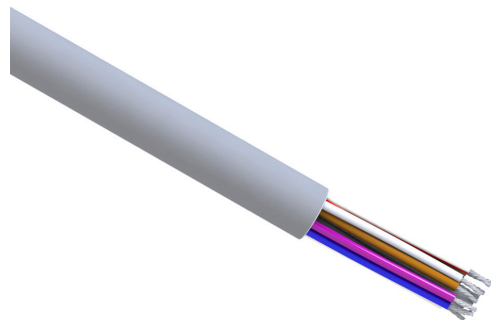

Quabbin control cable, unshielded, 15 conductors, 20 AWG, 7-stranded, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CC600-20-15U-1>

Technical Specifications

Brand	Quabbin
Item	Cable
Wire/Cable Type	Control
UL Wire/Cable Type	AWM
Applicable Standards	UL 2586
Application	General purpose
Flexibility	Flexible
Voltage Rating	600V rated (UL)
Conductors	15 conductors
Conductor Size	20 AWG
Conductor Stranding	7-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	PVC
Conductor Insulation Color	Black, brown, red, orange, yellow, green, blue, violet, gray, white, white/black, white/brown, white/red, white/orange and white/yellow

Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Gray
Nominal Overall Cable Diameter	0.395in
Bulk Length	Cut to length
Package Type	1 to 50ft = Coil, 51 to 250ft = 14 x 7in Reel, 251 to 350ft = 14 x 10in Reel, 351 to 550ft = 16 x 10in Reel, 551 to 780ft = 18 x 10in Reel, 781 to 1010ft = 18 x 13in Reel, 1011 to 2180ft = 24 x 17in Wooden Reel, 2181 to 3590ft = 30 x 17in Wooden Reel, 3591 to 5000ft = Large Wooden Reel

Agency Approvals

UL Listed File #	E69976
UL Recognized File #	None
UL Hazardous File #	None
CSA File #	LL51726
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement