


CC600-20-25U-1 Cut Sheet

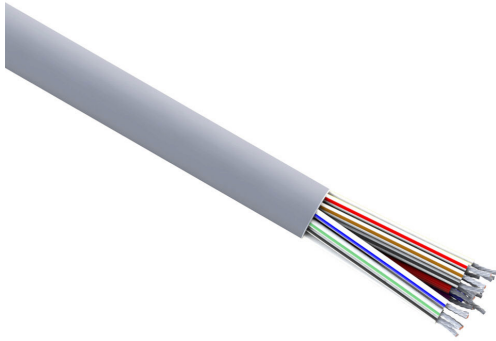

Quabbin control cable, unshielded, 25 conductors, 20 AWG, 7-stranded, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CC600-20-25U-1>

Technical Specifications

Brand	Quabbin	Shielding	Unshielded
Item	Cable	Jacket Material	PVC
Wire/Cable Type	Control	Jacket Color	Gray
UL Wire/Cable Type	AWM	Nominal Overall Cable Diameter	0.498in
Applicable Standards	UL 2586	Bulk Length	Cut to length
Application	General purpose	Package Type	<ul style="list-style-type: none">• 20 to 50ft = Coil• 51 to 155ft = 14 x 7in Reel• 156 to 225ft = 14 x 10in Reel• 226 to 345ft = 16 x 10in Reel• 346 to 480ft = 18 x 10in Reel• 481 to 625ft = 18 x 13in Reel• 626 to 1400ft = 24 x 17in Wooden Reel• 1401 to 2240ft = 30 x 17in Wooden Reel• 2241 to 5000ft = Large Wooden Reel
Flexibility	Flexible		
Voltage Rating	600V rated (UL)		
Conductors	25 conductors		
Conductor Size	20 AWG		
Conductor Stranding	7-stranded		
Conductor Material	Tinned copper		
Conductor Insulation Material	PVC		
Conductor Insulation Color	Black, brown, red, orange, yellow, green, blue, violet, gray, white, white/black, white/brown, white/red, white/orange, white/yellow, white/green, white/blue, white/violet, white/gray, white/black/brown, white/black/red, white/black/orange, white/black/yellow, white/black/green and white/black/blue		

Agency Approvals

UL Listed File #	E69976
UL Recognized File #	None
UL Hazardous File #	None
CSA File #	LL51726
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement