


CF10-UL-05-05-1 Cut Sheet

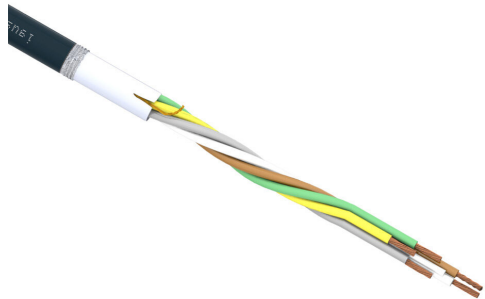

igus continuous flexing control cable, shielded, 5 conductors (includes ground), 20 AWG (0.50mm²), bare copper, TPE conductor insulation material, black with white numbers and green/yellow ground, TPE jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CF10-UL-05-05-1>

Technical Specifications

Brand	igus
Item	Cable
Wire/Cable Type	Control
UL Wire/Cable Type	AWM
Applicable Standards	UL 10258, UL 21387 and NFPA 79
Application	Automation
Flexibility	Continuous flexing
Voltage Rating	600V (AWM Style 10258), 1000V (AWM Style 21387)
Conductors	5 conductors (includes ground)
Conductor Size	20 AWG (0.50mm ²)
Conductor Stranding	28-stranded
Conductor Material	Bare copper
Conductor Insulation Material	TPE
Conductor Insulation Color	Black with white numbers and green/yellow ground

Shielding	Shielded
Jacket Material	TPE
Jacket Color	Gray
Nominal Overall Cable Diameter	0.354in
Bulk Length	Cut to length
Package Type	1 to 75ft = Coil, 76 to 310ft = 14 x 7in Reel, 311 to 440ft = 14 x 10in Reel, 441 to 690ft = 16 x 10in Reel, 691 to 970ft = 18 x 10in Reel, 971 to 1260ft = 18 x 13in Reel, 1261 to 2710ft = 24 x 17in Wooden Reel, 2711 to 4460ft = 30 x 17in Wooden Reel, 4461 to MAX = Large Wooden Reel

Agency Approvals

UL Listed File #	None
UL Recognized File #	E310776
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document