


CF11-01-04-02-1 Cut Sheet

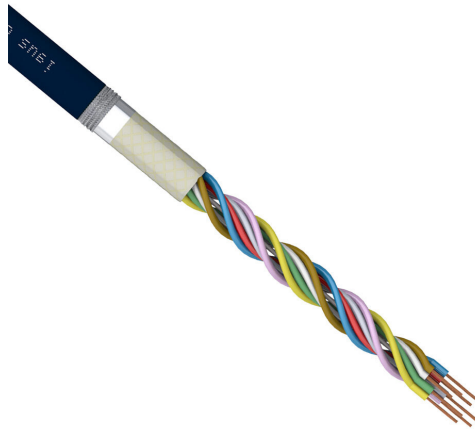

igus continuous flexing control and signal cable, shielded, 4 twisted pairs, 26 AWG (0.14mm²), 18-stranded, bare copper, TPE conductor insulation material, TPE jacket, blue, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CF11-01-04-02-1>

Technical Specifications

Brand	igus
Item	Cable
Wire/Cable Type	Control and signal
Application	General purpose
Flexibility	Continuous flexing
Voltage Rating	300V
Conductors	4 twisted pairs
Conductor Size	26 AWG (0.14mm ²)
Conductor Stranding	18-stranded
Conductor Material	Bare copper
Conductor Insulation Material	TPE
Conductor Insulation Color	Pair 1: white and brown, pair 2: green and yellow, pair 3: grey and pink and pair 4: blue and red

Shielding	Shielded
Jacket Material	TPE
Jacket Color	Blue
Nominal Overall Cable Diameter	0.295in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 1 to 50ft = Coil• 51 to 99ft = 14 x 7in Reel• 100 to 440ft = 14 x 10in Reel• 441 to 640ft = 16 x 10in Reel• 641 to 990ft = 18 x 10in Reel• 991 to 1390ft = 18 x 13in Reel• 1391 to 1615ft = 24 x 17in Wooden Reel

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document