


CF11-02-02-02-1 Cut Sheet

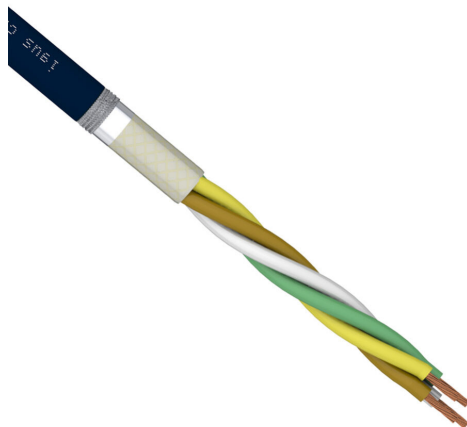

igus continuous flexing control and signal cable, shielded, 2 twisted pairs, 24 AWG (0.25mm²), bare copper, TPE conductor insulation material, pair 1: white and brown and pair 2: green and yellow, TPE jacket, blue, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CF11-02-02-02-1>

Technical Specifications

| | |
|---------------------------------------|--|
| Brand | igus |
| Item | Cable |
| Wire/Cable Type | Control and signal |
| Application | General purpose |
| Flexibility | Continuous flexing |
| Voltage Rating | 300V |
| Conductors | 2 twisted pairs |
| Conductor Size | 24 AWG (0.25mm ²) |
| Conductor Stranding | 32-stranded |
| Conductor Material | Bare copper |
| Conductor Insulation Material | TPE |
| Conductor Insulation Color | Pair 1: white and brown and pair 2: green and yellow |
| Shielding | Shielded |
| Jacket Material | TPE |
| Jacket Color | Blue |
| Nominal Overall Cable Diameter | 0.256in |
| Bulk Length | Cut to length |
| Package Type | <ul style="list-style-type: none">• 1 to 99ft = Coil• 100 to 590ft = 14 x 7in Reel• 591 to 850ft = 14 x 10in Reel• 851 to 1320ft = 16 x 10in Reel• 1321 to 1615ft = 18 x 10in Reel |

Agency Approvals

| | |
|-----------------------------|--|
| UL Listed File # | None |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | View CE declarations |
| CSA File # | None |
| RoHS Status | Yes (See CE Doc) |
| EU REACH | View EU REACH document |