


CF130US-07-04-1 Cut Sheet

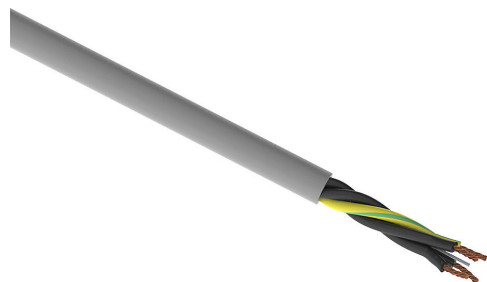

igus continuous flexing control cable, unshielded, 4 conductors (includes ground), 18 AWG (0.75mm²), bare copper, PVC/Nylon conductor insulation material, black with white numbers and green/yellow ground, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CF130US-07-04-1>

Technical Specifications

Brand	igus
Item	Cable
Wire/Cable Type	Control
UL Wire/Cable Type	TC, TC-ER, WTTTC and MTW
Applicable Standards	UL 1277 and UL 1685
Application	Automation
Flexibility	Continuous flexing
Voltage Rating	600V
Conductors	4 conductors (includes ground)
Conductor Size	18 AWG (0.75mm ²)
Conductor Stranding	24-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC/Nylon
Conductor Insulation Color	Black with white numbers and green/yellow ground

Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Gray
Nominal Overall Cable Diameter	0.33in
Bulk Length	Cut to length
Package Type	1 to 75ft = Coil, 76 to 350ft = 14 x 7in Reel, 351 to 510ft = 14 x 10in Reel, 511 to 790ft = 16 x 10in Reel, 791 to 1120ft = 18 x 10in Reel, 1121 to 1450ft = 18 x 13in Reel, 1451 to 3120ft = 24 x 17in Wooden Reel, 3121 to 5140ft = 30 x 17in Wooden Reel, 5141 to MAX = Large Wooden Reel

Agency Approvals

UL Listed File #	E223775
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	257958
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document