


CF140US-07-05-1 Cut Sheet

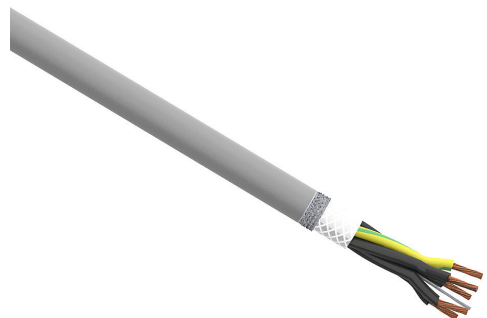

igus continuous flexing control cable, shielded, 5 conductors (includes ground), 18 AWG (0.75mm²), bare copper, PVC/Nylon conductor insulation material, black with white numbers and green/yellow ground, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CF140US-07-05-1>

Technical Specifications

Brand	igus
Item	Cable
Wire/Cable Type	Control
UL Wire/Cable Type	TC, TC-ER, WTTTC and MTW
Applicable Standards	UL 1277 and UL 1685
Application	Automation
Flexibility	Continuous flexing
Voltage Rating	600V
Conductors	5 conductors (includes ground)
Conductor Size	18 AWG (0.75mm ²)
Conductor Stranding	24-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC/Nylon
Conductor Insulation Color	Black with white numbers and green/yellow ground

Shielding	Shielded
Jacket Material	PVC
Jacket Color	Gray
Nominal Overall Cable Diameter	0.43in
Bulk Length	Cut to length
Package Type	1 to 50ft = Coil, 51 to 210ft = 14 x 7in Reel, 211 to 300ft = 14 x 10in Reel, 301 to 460ft = 16 x 10in Reel, 461 to 650ft = 18 x 10in Reel, 651 to 850ft = 18 x 13in Reel, 851 to 1840ft = 24 x 17in Wooden Reel, 1841 to 3020ft = 30 x 17in Wooden Reel, 3021 to MAX = Large Wooden Reel

Agency Approvals

UL Listed File #	E223775
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	257958
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document