


CF211-P-05-01-02-1 Cut Sheet

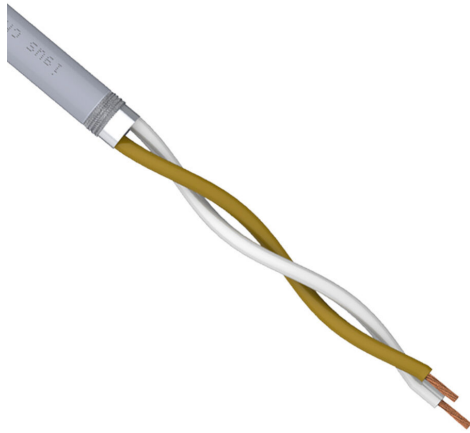

igus continuous flexing control and signal cable, shielded, AWM, 1 twisted pair, 20 AWG (0.50mm²), bare copper, TPE conductor insulation material, white and brown, PUR jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CF211-P-05-01-02-1>

Technical Specifications

Brand	igus
Item	Cable
Wire/Cable Type	Control and signal
UL Wire/Cable Type	AWM
Applicable Standards	UL 20233
Application	General purpose
Flexibility	Continuous flexing
Voltage Rating	300V
Conductors	1 twisted pair
Conductor Size	20 AWG (0.50mm ²)
Conductor Stranding	28-stranded
Conductor Material	Bare copper
Conductor Insulation Material	TPE

Conductor Insulation Color	White and brown
Shielding	Shielded
Jacket Material	PUR
Jacket Color	Gray
Nominal Overall Cable Diameter	0.236in
Bulk Length	Cut to length
Package Type	1 to 99ft = Coil, 100 to 700ft = 14 x 7in Reel, 701 to 1000ft = 14 x 10in Reel, 1001 to 1550ft = 16 x 10in Reel, 1551 to 1615ft = 18 x 10in Reel

Agency Approvals

UL Listed File #	None
UL Recognized File #	E310776
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document