


CF5-05-05-1 Cut Sheet

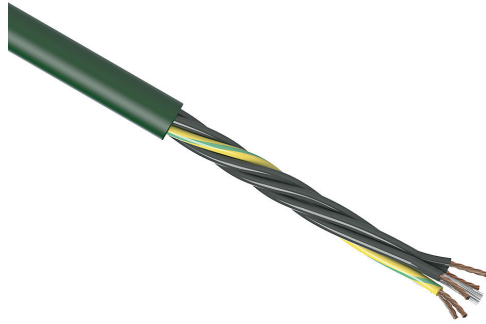

igus continuous flexing control cable, unshielded, 5 conductors (includes ground), 20 AWG (0.50mm²), bare copper, TPE conductor insulation material, black with white numbers and green/yellow ground, PVC jacket, green, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CF5-05-05-1>

Technical Specifications

Brand	igus
Item	Cable
Wire/Cable Type	Control
UL Wire/Cable Type	AWM
Applicable Standards	UL 10492, UL 2570 and NFPA 79
Application	Automation
Flexibility	Continuous flexing
Voltage Rating	600V
Conductors	5 conductors (includes ground)
Conductor Size	20 AWG (0.50mm ²)
Conductor Stranding	16-stranded
Conductor Material	Bare copper
Conductor Insulation Material	TPE
Conductor Insulation Color	Black with white numbers and green/yellow ground

Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Green
Nominal Overall Cable Diameter	0.276in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 1 to 99ft = Coil• 100 to 510ft = 14 x 7in Reel• 511 to 730ft = 14 x 10in Reel• 731 to 1140ft = 16 x 10in Reel• 1141 to 1600ft = 18 x 10in Reel• 1601 to 2080ft = 18 x 13in Reel• 2081 to 4480ft = 24 x 17in Wooden Reel• 4481 to 7370ft = 30 x 17in Wooden Reel• 7371 to MAX = Large Wooden Reel

Agency Approvals

UL Listed File #	E485487
UL Recognized File #	E310776
CE	View CE declarations
CSA File #	115172
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document