


CF5-07-03-1 Cut Sheet

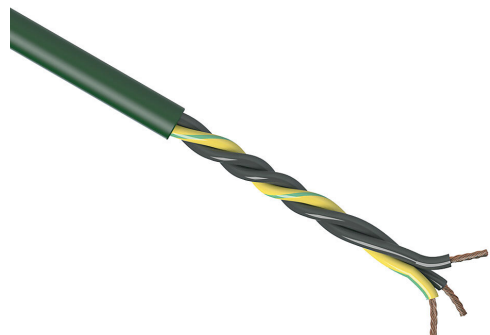

igus continuous flexing control cable, unshielded, 3 conductors (includes ground), 18 AWG (0.75mm²), bare copper, PVC conductor insulation material, black with white numbers and green/yellow ground, PVC jacket, green, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CF5-07-03-1>

Technical Specifications

Brand	igus
Item	Cable
Wire/Cable Type	Control
UL Wire/Cable Type	AWM
Applicable Standards	UL 11113, UL 2570 and NFPA 79
Application	Automation
Flexibility	Continuous flexing
Voltage Rating	600V
Conductors	3 conductors (includes ground)
Conductor Size	18 AWG (0.75mm ²)
Conductor Stranding	24-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC
Conductor Insulation Color	Black with white numbers and green/yellow ground

Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Green
Nominal Overall Cable Diameter	0.256in
Bulk Length	Cut to length
Package Type	1 to 99ft = Coil, 100 to 590ft = 14 x 7in Reel, 591 to 850ft = 14 x 10in Reel, 851 to 1320ft = 16 x 10in Reel, 1321 to 1860ft = 18 x 10in Reel, 1861 to 2420ft = 18 x 13in Reel, 2421 to 5200ft = 24 x 17in Wooden Reel, 5201 to 8550ft = 30 x 17in Wooden Reel, 8551 to MAX = Large Wooden Reel

Agency Approvals

UL Listed File #	E485487
UL Recognized File #	E310776
CE	View CE declarations
CSA File #	115172
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document