


CF9-UL-15-05-1 Cut Sheet

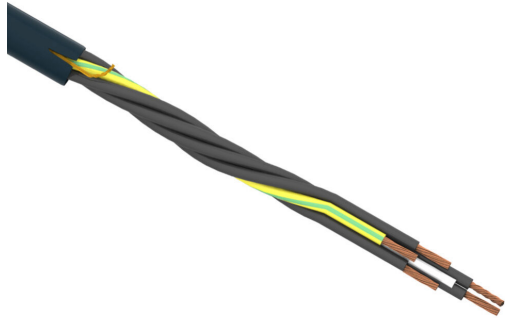

igus continuous flexing control cable, unshielded, 5 conductors (includes ground), 16 AWG (1.50mm²), bare copper, TPE conductor insulation material, black with white numbers and green/yellow ground, TPE jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CF9-UL-15-05-1>

Technical Specifications

Brand	igus
Item	Cable
Wire/Cable Type	Control
UL Wire/Cable Type	AWM
Applicable Standards	UL 10258, UL 21387 and NFPA 79
Application	Automation
Flexibility	Continuous flexing
Voltage Rating	600V (AWM Style 10258), 1000V (AWM Style 21387)
Conductors	5 conductors (includes ground)
Conductor Size	16 AWG (1.50mm ²)
Conductor Stranding	80-stranded
Conductor Material	Bare copper
Conductor Insulation Material	TPE
Conductor Insulation Color	Black with white numbers and green/yellow ground

Shielding	Unshielded
Jacket Material	TPE
Jacket Color	Gray
Nominal Overall Cable Diameter	0.374in
Bulk Length	Cut to length
Package Type	1 to 75ft = Coil, 76 to 280ft = 14 x 7in Reel, 281 to 400ft = 14 x 10in Reel, 401 to 610ft = 16 x 10in Reel, 611 to 870ft = 18 x 10in Reel, 871 to 1130ft = 18 x 13in Reel, 1131 to 2430ft = 24 x 17in Wooden Reel, 2431 to 4000ft = 30 x 17in Wooden Reel, 4001 to MAX = Large Wooden Reel

Agency Approvals

UL Listed File #	None
UL Recognized File #	E310776
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document