


CFW300-IOAR Cut Sheet

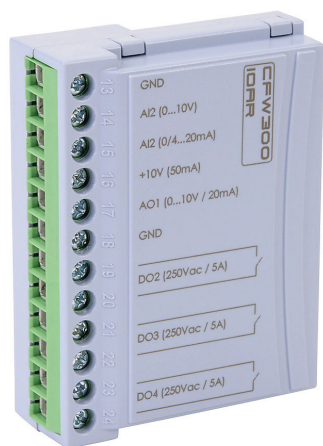

WEG Electric CFW300 series relay/analog combo module, Analog Input: 1-channel, current/voltage, Analog Output: 1-channel, current/voltage, Discrete Output: 3-point, relay, (3) Form A (SPST) relays. For use with WEG CFW300 series AC drives.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CFW300-IOAR>

Technical Specifications

Brand	WEG Electric
Item	Combo module
I/O Module Type	Relay/analog
Series	CFW300
Number of Analog Input Channels	1
Analog Input Signal Type	Current/voltage
Input Resolution	10-bit
Input Current Signal Range	0-20 mA and 4-20 mA
Input Voltage Signal Range	0-10 VDC
Number of Analog Output Channels	1
Analog Output Signal Type	Current/voltage
Output Resolution	12-bit
Output Current Signal Range	0-20 mA and 4-20 mA

Output Voltage Signal Range	0-10 VDC
Number of Discrete Output Points	3
Nominal Output Voltage	250 VAC
Discrete Output Type	Relay
Relay Configuration	(3) Form A (SPST) relays
Number of Isolated Discrete Output Commons	3
Number of Points per Discrete Output Common	1
Load Current	5A/point
For Use With	WEG CFW300 series AC drives

Agency Approvals

UL Listed File #	E184430
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/CFW300-IOAR.pdf>
See store item page for other formats.