


CFW300-IODR Cut Sheet

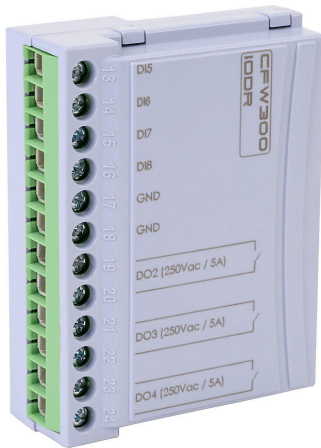

WEG Electric CFW300 series discrete combo module, Input: 4-point, 24 VDC, sinking/sourcing, Output: 3-point, 250 VAC, relay, (3) Form A (SPST) relays, 5A/point. For use with WEG CFW300 series AC drives.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CFW300-IODR>

Technical Specifications

Brand	WEG Electric
Item	Combo module
I/O Module Type	Discrete
Series	CFW300
Number of Input Points	4
Nominal Input Voltage	24 VDC
Discrete Input Type	Sinking/sourcing
Number of Non-Isolated Discrete Input Commons	2
Number of Points per Discrete Input Common	2

Number of Output Points	3
Nominal Output Voltage	250 VAC
Discrete Output Type	Relay
Relay Configuration	(3) Form A (SPST) relays
Number of Isolated Discrete Output Commons	3
Number of Points per Discrete Output Common	1
Load Current	5A/point
For Use With	WEG CFW300 series AC drives

Agency Approvals

UL Listed File #	E184430
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/CFW300-IODR.pdf>
See store item page for other formats.