


CMV-D1X-3X Cut Sheet

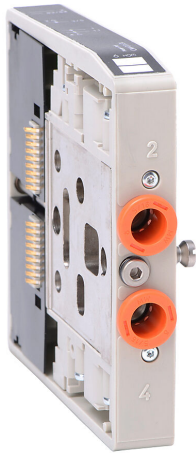

NITRA pneumatic modular plate, intermediate through, Cv=0.65, 5/16in (8mm) push-to-connect inlet(s), 5/16in (8mm) PTC tubing exhaust(s), reinforced technopolymer body, IP65.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CMV-D1X-3X>

Technical Specifications

Brand	NITRA
Item	Modular plate
Working Fluid	Air or inert gas
Pneumatic Function	Intermediate through
Flow Coefficient	0.65
Inlet Port	5/16in (8mm) push-to-connect
Exhaust Port	5/16in (8mm) PTC tubing
Body Material	Reinforced technopolymer
IP Rating	IP65
For Use With	CMV series solenoid valves

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/CMV-D1X-3X.pdf>
See store item page for other formats.