


CPS-CP-A Cut Sheet

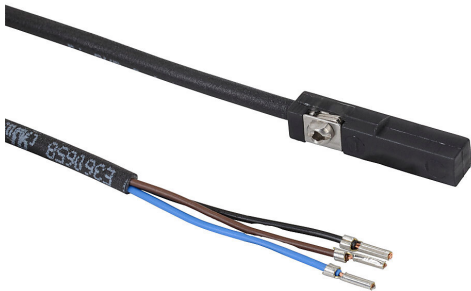

NITRA cylinder switch, square, PNP, N.C. output, 10-30 VDC operating voltage, LED indication, 2m (6.56ft) 3-wire pigtail with wire leads, straight cable entry, 5mm square T-slot mount, for position sensing.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CPS-CP-A>

Technical Specifications

Brand	NITRA
Item	Cylinder switch
Shape	Square
Output	PNP, N.C.
Operating Voltage	10-30 VDC
Indicating Type	LED indication
Electrical Connection	2m (6.56ft) 3-wire pigtail with wire leads
Cable Entry	Straight
Mounting	5mm square T-slot
Application	For position sensing
Additional Information	Use a CPSB series mounting band for round body cylinders or a CPSA series rod adapter for tie rod cylinders

Agency Approvals

UL Listed File #	E328811
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/CPS-CP-A.pdf>
See store item page for other formats.