


CPS9F-AP-A Cut Sheet

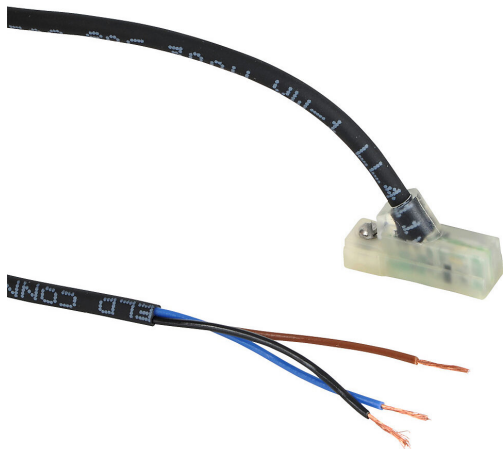

NITRA cylinder switch, rectangular, PNP, N.O. output, 5-28 VDC operating voltage, LED indication, 9.8ft (3.00m) 3-wire pigtail with wire leads, 6.5 x 3.2mm T-slot mount, for position sensing.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CPS9F-AP-A>

Technical Specifications

Brand	NITRA
Item	Cylinder switch
Shape	Rectangular
Output	PNP, N.O.
Operating Voltage	5-28 VDC
Indicating Type	LED indication
Electrical Connection	9.8ft (3.00m) 3-wire pigtail with wire leads
Mounting	6.5 x 3.2mm T-slot
Application	For position sensing

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document