


# CWB40-11-30D39 Cut Sheet

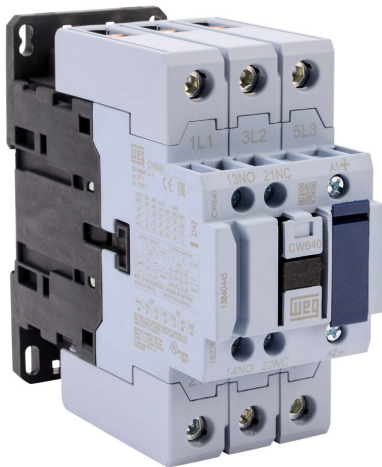

WEG Electric CWB series IEC contactor, 40A, (3) N.O. power poles, (1) N.O./1) N.C. auxiliary contacts, 480 VAC (50/60Hz) coil voltage.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CWB40-11-30D39>

## Technical Specifications

|                           |                        |
|---------------------------|------------------------|
| <b>Brand</b>              | WEG Electric           |
| <b>Item</b>               | Contactor              |
| <b>Series</b>             | CWB                    |
| <b>Contactor Type</b>     | IEC                    |
| <b>Actuator Type</b>      | Magnetic               |
| <b>Amperage Rating</b>    | 40A                    |
| <b>Power Poles</b>        | (3) N.O.               |
| <b>Auxiliary Contacts</b> | (1) N.O./1) N.C.       |
| <b>Coil Voltage</b>       | 480 VAC (50/60Hz)      |
| <b>Horsepower Rating</b>  | 30hp                   |
| <b>SCCR Rating</b>        | 5kA SCCR               |
| <b>UL Rating</b>          | UL 508 rated           |
| <b>Mounting</b>           | 35mm DIN rail or panel |

## Agency Approvals

|                             |  |
|-----------------------------|--|
| <b>UL Listed File #</b>     | E202315                                |
| <b>UL Recognized File #</b> | None                                   |
| <b>UL Hazardous File #</b>  | None                                   |
| <b>CE</b>                   | <a href="#">View CE declarations</a>   |
| <b>CSA File #</b>           | None                                   |
| <b>RoHS Status</b>          | Yes (See CE Doc)                       |
| <b>EU REACH</b>             | <a href="#">View EU REACH document</a> |