


CWF6S-24-CD Cut Sheet



Patlite LED light bar, 600mm length, 24 VDC operating voltage, on/off switch, daylight white, bracket mount, pigtail, polycarbonate/aluminum body, 9.8ft/3m cable length, IP20. Mounting bracket included.

For complete product information, please see this item on our store at the following link:

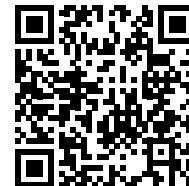

<https://www.automationdirect.com/pn/CWF6S-24-CD>

Technical Specifications

Brand	Patlite
Item	LED light bar
Length	600mm
Operating Voltage	24 VDC
Switch Type	On/off
LED Color	Daylight white
Color Temperature	5700K
Mounting	Bracket
Connection	Pigtail
Power Consumption	10W
Body Material	Polycarbonate/aluminum
Cable Length	9.8ft/3m
IP Rating	IP20
Includes	Mounting bracket

Agency Approvals

UL Listed File #	E306141
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	NONE
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document
Other	None