


D0-10TD1 Cut Sheet

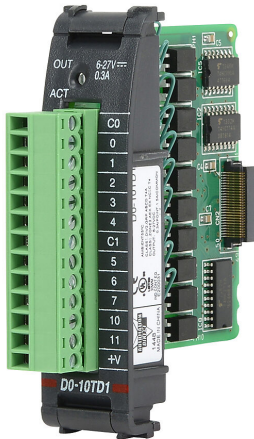

DirectLOGIC DL05/06 discrete output module, 10-point, 6-24 VDC, sinking, 2 common(s), 5 point(s) per common, 0.3A/point, 1.5A/common. Removable terminal block included.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/D0-10TD1>

Technical Specifications

| | |
|--|---|
| Brand | DirectLOGIC |
| Item | Output module |
| I/O Module Type | Discrete |
| Series | DL05/06 |
| Number of Output Points | 10 |
| Nominal Output Voltage | 6-24 VDC |
| Discrete Output Type | Sinking |
| Number of Non-Isolated Output Commons | 2 |
| Number of Points per Common | 5 |
| Load Current | 0.3A/point, 1.5A/common |
| Fuse Type | User-supplied external fuse |
| Includes | Removable terminal block |
| Programming Software | DirectSOFT programming software v4.0 or later |

Agency Approvals

| | |
|-----------------------------|--|
| UL Listed File # | E157382 |
| UL Recognized File # | None |
| UL Hazardous File # | E200031 |
| CE | View CE declarations |
| CSA File # | None |
| RoHS Status | Yes (See CE Doc) |
| EU REACH | View EU REACH document |