


# DC6234 Cut Sheet

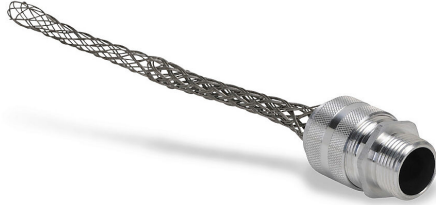

Bryant deluxe strain relief grip, accepts cable diameter size 0.62 to 0.75in, straight 3/4in NPT male thread fitting, stainless steel mesh, 6.31in length, indoor and outdoor applications.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/DC6234>

## Technical Specifications

<b>Brand</b>	Bryant
<b>Item</b>	Cord grip
<b>Grip Type</b>	Strain relief
<b>Application</b>	Deluxe
<b>Low Tension</b>	No
<b>Cable Diameter Size</b>	0.62 to 0.75in
<b>Thread Size</b>	Straight 3/4in NPT male thread fitting
<b>Mesh Material</b>	Stainless steel
<b>Mesh Length</b>	6.31in
<b>Body Material</b>	Aluminum
<b>Collar Material</b>	Aluminum
<b>Bushing Material</b>	Neoprene
<b>Environmental Requirements</b>	Indoor and outdoor applications

## Agency Approvals

<b>UL Listed File #</b>	E167220
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	None
<b>CSA File #</b>	701228
<b>RoHS Status</b>	No
<b>EU REACH</b>	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/DC6234.pdf>  
See store item page for other formats.