


DET.11.2124 Cut Sheet

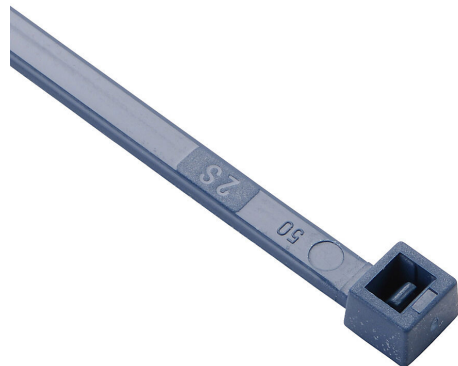

SapiSelco metal detectable cable tie, 9.84in length, 0.18in width, 55.12lb tensile strength, 2.68in maximum bundle diameter, blue, nylon. Package of 100.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/DET.11.2124>

Technical Specifications

Brand	SapiSelco
Item	Cable tie
Cable Tie Type	Metal detectable
Length	9.84in
Width	0.18in
Tensile Strength	55.12lb
Maximum Bundle Diameter	2.68in
Color	Blue
Material	Nylon
Temperature Rating	-40 to +185 deg F
Quantity per Pack	100

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document