


# DIN14-P10 Cut Sheet

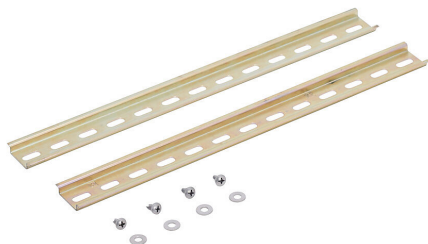

Integra DIN rail, slotted, 35mm, 7mm height, 12.8in length, plated steel. Package of 2. For use with 14in wide Premium series polycarbonate enclosures.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/DIN14-P10>

## Technical Specifications

Brand	Integra
Item	DIN rail
Slotted	Yes
DIN Rail Type	35mm
Height	7mm
Length	12.8in
Material	Plated steel
Quantity per Pack	2
For Use With	14in wide Premium series polycarbonate enclosures
Includes	Mounting hardware

## Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/DIN14-P10.pdf>  
See store item page for other formats.