


DN-24J4Y Cut Sheet

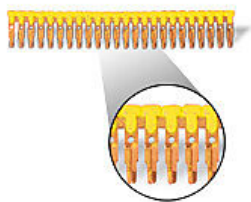

DINnector terminal block jumper, push-in type, 24-pole, yellow, 25A, 600V rated (UL). Package of 5. For use with DN-T10-A, DN-D10-A, DN-M10-A and DN-Q10-A series terminal block.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/DN-24J4Y>

Technical Specifications

Brand	DINnector
Item	Terminal block jumper
Jumper Type	Push-in
Number of Poles	24
Color	Yellow
Amperage Rating	25A
Voltage Rating	600V rated (UL)
Quantity per Pack	5
For Use With	DN-T10-A, DN-D10-A, DN-M10-A and DN-Q10-A series terminal block

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/DN-24J4Y.pdf>
See store item page for other formats.