


# DN-EMXDV Cut Sheet

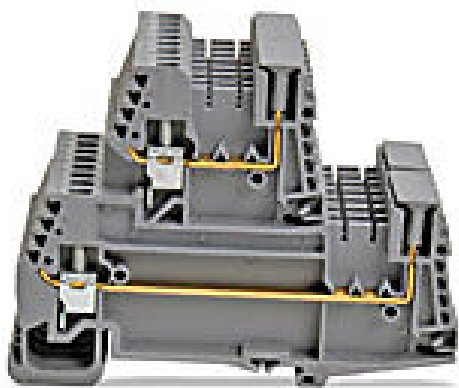

DINnector screw plug-in double-level feedthrough terminal block, accepts wire size 24-12 AWG, gray, 12A, 35mm DIN rail mount, 10kA SCCR. Package of 32.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/DN-EMXDV>

## Technical Specifications

Brand	DINnector
Item	Terminal block
Connector Type	Screw
Terminal Block Type	Plug-in double-level feedthrough
Wire Size	24-12 AWG
Color	Gray
Amperage Rating	12A
Voltage Rating	300V rated (UL)
Mounting	35mm DIN rail
SCCR Rating	10kA SCCR
Quantity per Pack	32
Includes	4-pin protectors (DN-EMPEG1)

## Agency Approvals

UL Listed File #	None
UL Recognized File #	E179129
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>