


DN-T12BR-A Cut Sheet

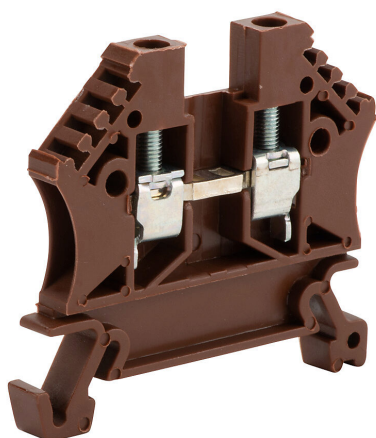

DINnector screw single-level feedthrough terminal block, accepts wire size 24-12 AWG, brown, 20A, 35mm DIN rail mount, 100kA SCCR. Package of 100. For use with jumpers DN-24J2Y, DN-2J2Y and DN-3J2Y.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/DN-T12BR-A>

Technical Specifications

| | |
|---------------------|---------------------------------------|
| Brand | DINnector |
| Item | Terminal block |
| Connector Type | Screw |
| Terminal Block Type | Single-level feedthrough |
| Wire Size | 24-12 AWG |
| Color | Brown |
| Amperage Rating | 20A |
| Voltage Rating | 600V rated (UL) |
| Mounting | 35mm DIN rail |
| SCCR Rating | 100kA SCCR |
| Quantity per Pack | 100 |
| For Use With | Jumpers DN-24J2Y, DN-2J2Y and DN-3J2Y |

Agency Approvals

| | |
|----------------------|--|
| UL Listed File # | None |
| UL Recognized File # | E179129 |
| UL Hazardous File # | None |
| CE | View CE declarations |
| CSA File # | None |
| RoHS Status | Yes (See CE Doc) |
| EU REACH | View EU REACH document |

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/DN-T12BR-A.pdf>
See store item page for other formats.