


DN-T8GRN Cut Sheet

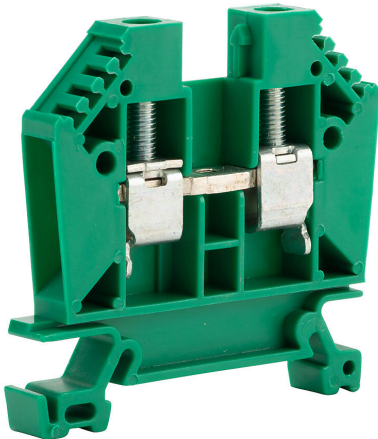

DINnector screw single-level feedthrough terminal block, accepts wire size 22-8 AWG, green, 50A, 35mm DIN rail mount, 100kA SCCR. Package of 50.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/DN-T8GRN>

Technical Specifications

| | |
|---------------------|--------------------------|
| Brand | DINnector |
| Item | Terminal block |
| Connector Type | Screw |
| Terminal Block Type | Single-level feedthrough |
| Wire Size | 22-8 AWG |
| Color | Green |
| Amperage Rating | 50A |
| Voltage Rating | 600V rated (UL) |
| Mounting | 35mm DIN rail |
| SCCR Rating | 100kA SCCR |
| Quantity per Pack | 50 |

Agency Approvals

| | |
|----------------------|--|
| UL Listed File # | None |
| UL Recognized File # | E179129 |
| UL Hazardous File # | None |
| CE | View CE declarations |
| CSA File # | None |
| RoHS Status | Yes (See CE Doc) |
| EU REACH | View EU REACH document |