


DN-TL14SLN-A Cut Sheet

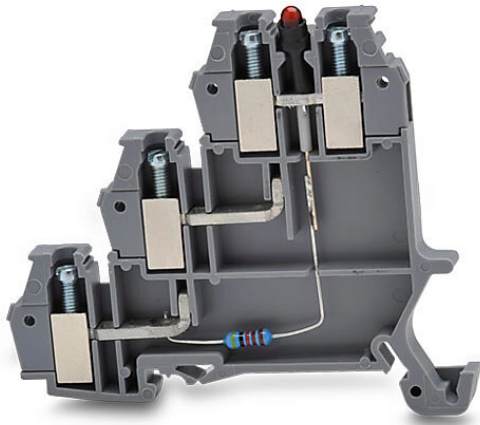

DINnector screw triple-level sensor terminal block, power indicator, accepts wire size 26-14 AWG, gray, 10A, NPN LED indicator(s), 35mm DIN rail mount, 10kA SCCR. Package of 25.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/DN-TL14SLN-A>

Technical Specifications

Brand	DINnector
Item	Terminal block
Connector Type	Screw
Terminal Block Type	Triple-level sensor
Terminal Block Special Feature(s)	Power indicator
Wire Size	26-14 AWG
Color	Gray
Amperage Rating	10A

Voltage Rating	300V rated (UL)
Indicator	NPN LED
Mounting	35mm DIN rail
SCCR Rating	10kA SCCR
Quantity per Pack	25
For Use With	Jumpers DN-12JL14B-A, DN-12JL14-A, DN-2JL14B-A, DN-2JL14-A, DN-3JL14B-A, and DN-3JL14-A
Application	For NPN type sensors

Agency Approvals

UL Listed File #	None
UL Recognized File #	E179129
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/DN-TL14SLN-A.pdf>
See store item page for other formats.