


# DPER08 Cut Sheet

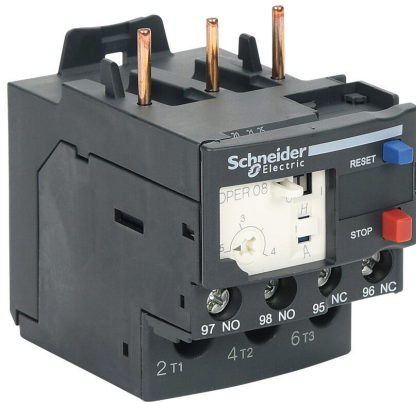

Schneider Electric Easy TeSys series thermal overload relay, 2.5-4A adjustable, bi-metallic, direct mount power connection(s). For use with Schneider Electric DPE09 to DPE38 contactors.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/DPER08>

## Technical Specifications

<b>Brand</b>	Schneider Electric
<b>Item</b>	Relay
<b>Series</b>	Easy TeSys
<b>Relay Type</b>	Thermal overload
<b>Full Load Amperage Range</b>	2.5-4A adjustable
<b>Operation Type</b>	Bi-metallic
<b>Auxiliary Contacts</b>	(1) N.O./ (1) N.C.
<b>Trip Class</b>	Trip Class 10
<b>Phase Loss Sensitive</b>	Yes
<b>Ground Fault Protection</b>	No
<b>Connection</b>	Direct mount power
<b>For Use With</b>	Schneider Electric DPE09 to DPE38 contactors

## Agency Approvals

<b>UL Listed File #</b>	E164353
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	164581
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/2d/DPER08.pdf>  
See store item page for other formats.