


# DPM-RS485 Cut Sheet

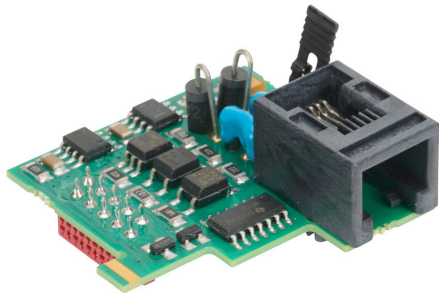

ProSense communication module, Modbus RTU and ASCII, 1 port, (1) RS-485 (RJ12) port(s). For use with ProSense DPM4 series panel meters. 6 ft connection cable and splitter included.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/DPM-RS485>

## Technical Specifications

|                                           |                                                                                                                |
|-------------------------------------------|----------------------------------------------------------------------------------------------------------------|
| Brand                                     | ProSense                                                                                                       |
| Item                                      | Communication module                                                                                           |
| Number of Ports                           | 1                                                                                                              |
| Communication Port and Connection Type(s) | (1) RS-485 (RJ12)                                                                                              |
| Port Protocol(s)                          | <ul style="list-style-type: none"><li>• Modbus RTU Slave</li><li>• ASCII In</li><li>• ISO 1745 Slave</li></ul> |
| Port Speed(s)                             | up to 19.2k baud                                                                                               |
| For Use With                              | ProSense DPM4 series panel meters                                                                              |
| Includes                                  | 6 ft connection cable and splitter                                                                             |

## Agency Approvals

|                      |                                        |
|----------------------|----------------------------------------|
| UL Listed File #     | None                                   |
| UL Recognized File # | None                                   |
| UL Hazardous File #  | None                                   |
| CE                   | <a href="#">View CE declarations</a>   |
| CSA File #           | None                                   |
| RoHS Status          | Yes (See CE Doc)                       |
| EU REACH             | <a href="#">View EU REACH document</a> |