


# DVD-2AC4A-24D Cut Sheet

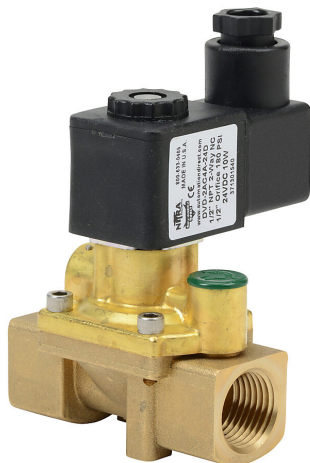

NITRA solenoid valve, 2-way, 2-position, N.C., brass body, 1/2in female NPT inlet(s), 1/2in female NPT outlet(s), Cv=2.45, 24 VDC operating voltage, 18mm DIN style wiring plug.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/DVD-2AC4A-24D>

## Technical Specifications

<b>Brand</b>	NITRA
<b>Item</b>	Valve
<b>Working Fluid</b>	Air, oil, inert gas, water or emulsion
<b>Valve Type</b>	Solenoid process
<b>Port Quantity</b>	2-way
<b>Number Of Positions</b>	2
<b>Valve Configuration</b>	N.C.
<b>Action</b>	Single solenoid spring return
<b>Body Material</b>	Brass
<b>Inlet Port</b>	1/2in female NPT
<b>Outlet Port</b>	1/2in female NPT
<b>Manual Override Type</b>	Momentary
<b>Flow Coefficient</b>	2.45
<b>Operating Voltage</b>	24 VDC
<b>Electrical Connection</b>	18mm DIN style wiring plug
<b>Form Factor</b>	Standard
<b>Includes</b>	Viton seals

## Agency Approvals

<b>UL Listed File #</b>	None
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	None
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>