


EA-MG-PGM-CBL Cut Sheet

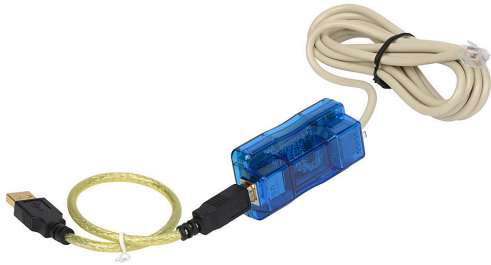

AutomationDirect programming cable assembly, USB A to 6-pin RJ12, 6ft cable length. For use with C-more Micro panels, CLICK CPUs, Do-more H2 series CPUs, and DirectLOGIC CPUs.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/EA-MG-PGM-CBL>

Technical Specifications

Brand	AutomationDirect
Item	Programming Cable assembly
Connection 1	USB A
Connection 2	6-pin RJ12
Shielded	No
Cable Length	6ft
For Use With	C-more Micro panels, CLICK CPUs, Do-more H2 series CPUs, and DirectLOGIC CPUs
Includes	(1) standard USB Type A to Type B connector cable, (1) custom converter and (1) RS-232C cable with RJ12 modular connector on each end
Additional Information	This cable assembly uses the PC's USB port and converts the signals to serial transmissions. The USB port supplies 5VDC to the C-more Micro panel for configuration operations

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/EA-MG-PGM-CBL.pdf>
See store item page for other formats.