


EVT426 Cut Sheet

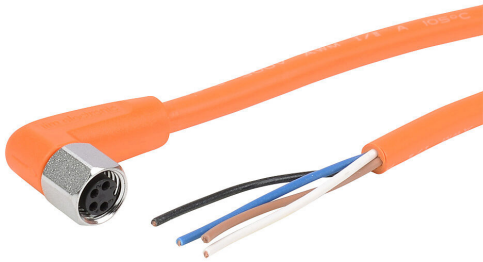

AutomationDirect connection cable, M8 right-angle female to pigtail, 4-pole, PVC jacket, orange, 32.8ft/10m cable length, IP65, IP67, IP68 and IP69K, suitable for food and beverage applications.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/EVT426>

Technical Specifications

Brand	AutomationDirect
Item	Cable
Cable Type	Connection
Connection 1	M8 right-angle female
Connection 2	Pigtail
Number of Poles	4
Jacket Material	PVC
Jacket Color	Orange
Cable Length	32.8ft/10m
IP Rating	IP65, IP67, IP68 and IP69K
Application	Suitable for food and beverage applications

Agency Approvals

UL Listed File #	E191684
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/EVT426.pdf>
See store item page for other formats.