


F3-04ADS Cut Sheet

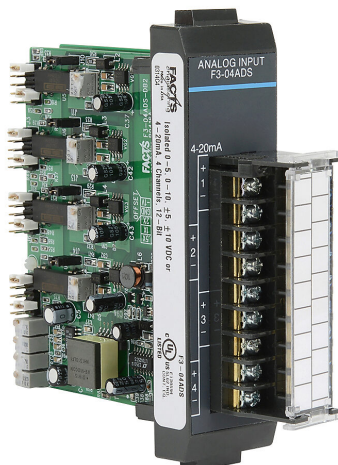

DirectLOGIC DL305 analog input module, 4-channel, current/voltage, 12-bit, isolated, input current signal range(s) of 0-20 mA, 4-20 mA, input voltage signal range(s) of 0-5 VDC, 0-10 VDC, 1-5 VDC, +/- 5 VDC, +/- 10 VDC.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/F3-04ADS>

Technical Specifications

Brand	DirectLOGIC
Item	Input module
I/O Module Type	Analog
Series	DL305
Number Of Input Channels	4
Input Signal Type(s)	Current/voltage
Analog Input Type	Sinking
Number of Isolated Commons	4
Isolated Channels	Yes
Input Resolution	12-bit
Input Current Signal Range	0-20 mA, 4-20 mA
Input Voltage Signal Range	0-5 VDC, 0-10 VDC, 1-5 VDC, +/- 5 VDC, +/- 10 VDC
Programming Software	DirectSOFT programming software v4.0 or later

Agency Approvals

UL Listed File #	E139594
UL Recognized File #	None
UL Hazardous File #	None
CE	None
RoHS Status	No
EU REACH	View EU REACH document