


FBM-RS-0P-0F Cut Sheet

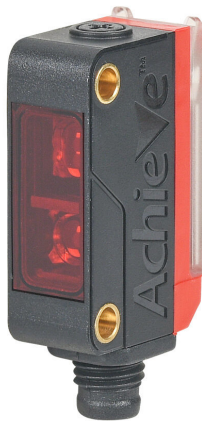

AchieVe photoelectric sensor, rectangular, diffuse with background suppression, 2–400mm sensing distance, selectable light-on/dark-on, PNP, potentiometer, 1 kHz switching frequency, 4-pin M8 quick-disconnect.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/FBM-RS-0P-0F>

Technical Specifications

Brand	AchieVe
Item	Photoelectric sensor
Shape	Rectangular
Housing Size	20 x 11 x 32.4mm
IP Rating	IP67
Application	Standard duty
Housing Material	ABS/polycarbonate
Sensing Method	Diffuse with background suppression
Operating Voltage	10–30 VDC
Number of Wires	3

Switching Output	PNP
Sensing Distance	2–400mm
Sensitivity	Potentiometer
Operation Mode	Selectable light-on/dark-on
Switching Frequency	1 kHz
Light Emission	Visible red
IO-Link Compatible	No
User Interface	Potentiometer adjustment
Connection	4-pin M8 quick-disconnect
Additional Information	Purchase cable separately

Agency Approvals

UL Listed File #	E328811
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/FBM-RS-0P-0F.pdf>
See store item page for other formats.