


# FC-33 Cut Sheet

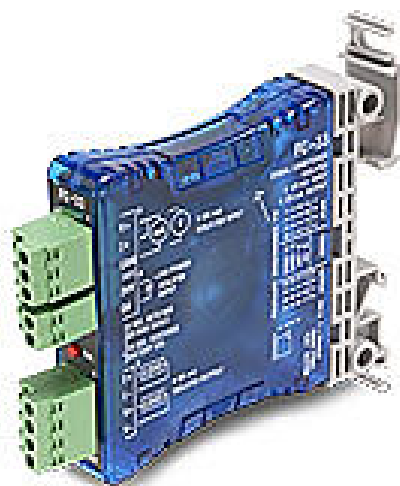

Signal conditioner, isolated, current or voltage input, current or voltage output, 24 VDC operating voltage, 35mm DIN rail or panel mount, removable screw terminal plugs.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/FC-33>

## Technical Specifications

Item	Signal conditioner
Isolation	Isolated
Field Configurable	Yes
Input Current Signal Range	0-20 mA, 4-20 mA
Input Voltage Signal Range	0-5 VDC, 0-10 VDC
Output Current Signal Range	0-20 mA and 4-20 mA
Output Voltage Signal Range	0-5 VDC and 0-10 VDC
Operating Voltage	24 VDC
Housing Material	Plastic
Mounting	35mm DIN rail or panel
Electrical Connection	Removable screw terminal plugs

## Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	E200031
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>