


FC-35B Cut Sheet

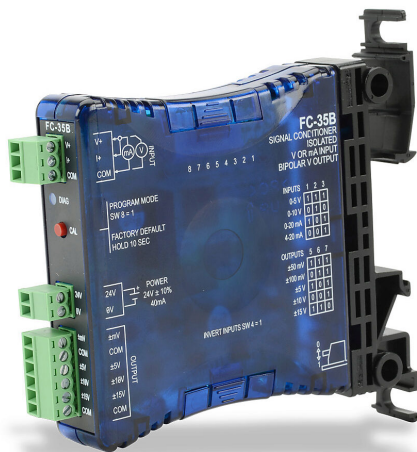

AutomationDirect signal conditioner, isolated, current or voltage input, bipolar voltage output, 24 VDC operating voltage, 35mm DIN rail or panel mount, removable screw terminal plugs.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/FC-35B>

Technical Specifications

Brand	AutomationDirect
Item	Signal conditioner
Isolation	Isolated
Field Configurable	Yes
Input Current Signal Range	Input current signal range(s) of 0-20 mA, 4-20 mA
Input Voltage Signal Range	Input voltage signal range(s) of 0-5 VDC, 0-10 VDC
Output Voltage Signal Range	+/- 100 mVDC, +/- 50 mVDC, +/- 5 VDC, +/- 10 VDC and +/- 15 VDC
Operating Voltage	24 VDC
Housing Material	Plastic
Mounting	35mm DIN rail or panel
Electrical Connection	Removable screw terminal plugs

Agency Approvals

UL Listed File #	E157382
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/FC-35B.pdf>
See store item page for other formats.