


FC-35B Cut Sheet

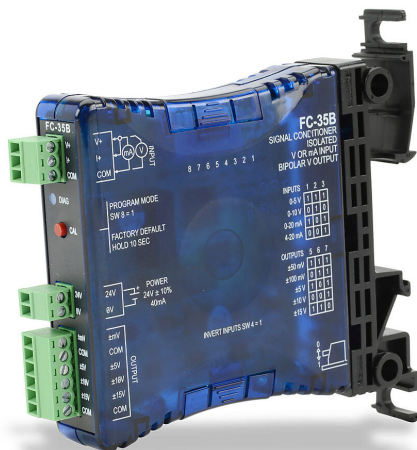

AutomationDirect signal conditioner, isolated, Input: 1-channel, current/voltage, Output: 1-channel, bipolar voltage, 24 VDC operating voltage, 35mm DIN rail or panel mount.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/FC-35B>

Technical Specifications

Brand	AutomationDirect
Item	Signal conditioner
Isolation	Isolated
Field Configurable	Yes
Number Of Input Channels	1
Input	Current/voltage
Input Current Signal Range	0-20 mA and 4-20 mA
Input Voltage Signal Range	0-5 VDC and 0-10 VDC

Number Of Output Channels	1
Output	Bipolar voltage
Output Voltage Signal Range	+/- 100 mVDC, +/- 50 mVDC, +/- 5 VDC, +/- 10 VDC and +/- 15 VDC
Operating Voltage	24 VDC
Housing Material	Plastic
Mounting	35mm DIN rail or panel
Electrical Connection	Removable screw terminal plugs

Agency Approvals

UL Listed File #	E157382
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/FC-35B.pdf>
See store item page for other formats.