


# FC-ISO-C Cut Sheet

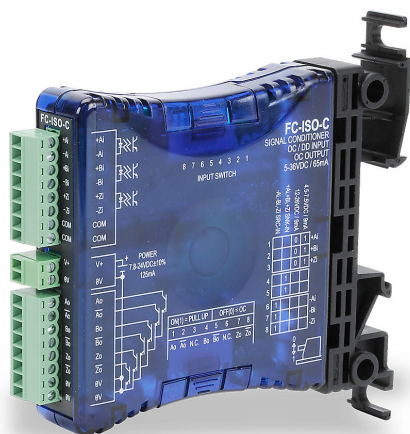

Signal conditioner, isolated, differential or single ended line driver input, open collector output, 7.8 to 24 VDC operating voltage, 35mm DIN rail or panel mount, removable screw terminal plugs.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/FC-ISO-C>

## Technical Specifications

Item	Signal conditioner
Isolation	Isolated
Field Configurable	Yes
Input High Speed Type	(3) 1 MHz @ 4.5-7.5 VDC/12-26 VDC differential or single ended line driver
Output High Speed Type	(3) 1 MHz @ 5-36 VDC open collector
Operating Voltage	7.8 to 24 VDC
Housing Material	Plastic
Mounting	35mm DIN rail or panel
Electrical Connection	Removable screw terminal plugs
Application	For encoders

## Agency Approvals

UL Listed File #	E157382
UL Recognized File #	None
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>