


G25-SDV-4CS Cut Sheet

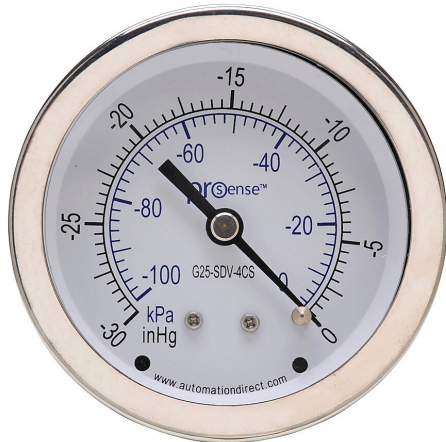

ProSense mechanical pressure gauge, 2.5in diameter, -30 to 0in Hg vacuum/-100 to 0 kPa, stainless steel dry case, stainless steel wetted parts, 1/4in male NPT process connection, center back mount.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/G25-SDV-4CS>

Technical Specifications

| | |
|---------------------------|------------------------------------|
| Brand | ProSense |
| Item | Mechanical pressure gauge |
| Diameter | 2.5in |
| Scale | -30 to 0in Hg vacuum/-100 to 0 kPa |
| Case Type | Stainless steel dry |
| Wetted Parts | Stainless steel |
| Process Connection | 1/4in male NPT |
| Mounting | Center back |

Agency Approvals

| | |
|-----------------------------|--|
| UL Listed File # | None |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | None |
| CSA File # | None |
| RoHS Status | No |
| EU REACH | View EU REACH document |