


G25-SL2000-4LB Cut Sheet

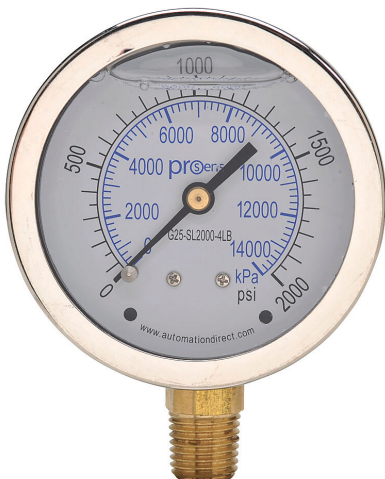

ProSense mechanical pressure gauge, 2.5in diameter, 0 to 2000 psig/0 to 14000 kPa, stainless steel liquid filled case, brass wetted parts, 1/4in male NPT process connection, lower mount.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/G25-SL2000-4LB>

Technical Specifications

Brand	ProSense
Item	Mechanical pressure gauge
Diameter	2.5in
Scale	0 to 2000 psig/0 to 14000 kPa
Case Type	Stainless steel liquid filled
Wetted Parts	Brass
Process Connection	1/4in male NPT
Mounting	Lower

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/G25-SL2000-4LB.pdf>
See store item page for other formats.