


# G25-SL300-4LS Cut Sheet

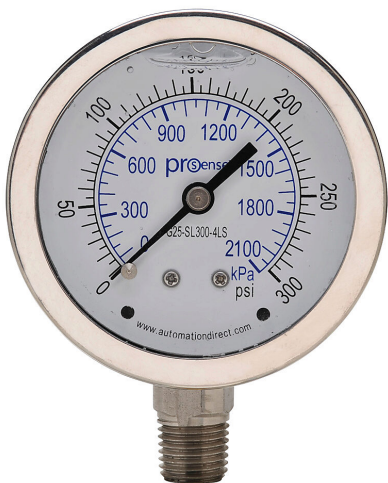

ProSense mechanical pressure gauge, 2.5in diameter, 0 to 300 psig/0 to 2100 kPa, stainless steel liquid filled case, stainless steel wetted parts, 1/4in male NPT process connection, lower mount.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/G25-SL300-4LS>

## Technical Specifications

Brand	ProSense
Item	Mechanical pressure gauge
Diameter	2.5in
Scale	0 to 300 psig/0 to 2100 kPa
Case Type	Stainless steel liquid filled
Wetted Parts	Stainless steel
Process Connection	1/4in male NPT
Mounting	Lower

## Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/G25-SL300-4LS.pdf>  
See store item page for other formats.