


GCBX2-FHC-N4X-M Cut Sheet

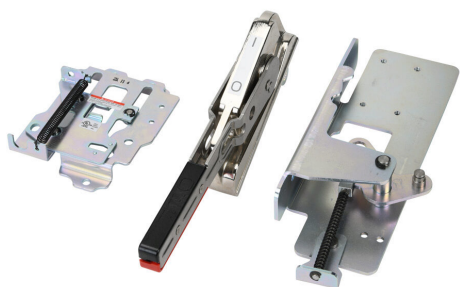

Gladiator flange handle, lever, chrome, external front mount, 2-position, lockable in OFF only, defeatable, NEMA 3/4/4X. For use with Gladiator 150A and 250A frame MCCBs. Operating mechanism included.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/GCBX2-FHC-N4X-M>

Technical Specifications

| | |
|----------------------------|-------------------------------------|
| Brand | Gladiator |
| Item | Handle |
| Handle Type | Flange |
| Handle Style | Lever |
| Color | Chrome |
| Mounting | External front |
| Number Of Positions | 2 |
| Lockable Positions | OFF only |
| Defeatable | Yes |
| NEMA Rating | 3/4/4X |
| Test Function | No |
| For Use With | Gladiator 150A and 250A frame MCCBs |
| Includes | Operating mechanism |
| Requires | Cable GCBX2-CBL-XX |

Agency Approvals

| | |
|-----------------------------|----------------------------------------|
| UL Listed File # | E509077 |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | View CE declarations |
| CSA File # | None |
| RoHS Status | Yes (See CE Doc) |
| EU REACH | View EU REACH document |