


GCX1284-120L Cut Sheet

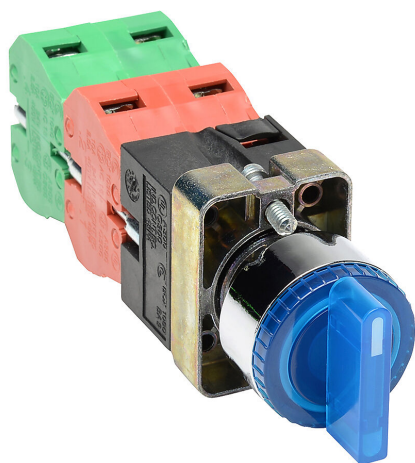

AutomationDirect selector switch, 22mm, 3-position, spring return to center, LED illuminated, (2) N.O./ (2) N.C. contact(s), metal base, metal bezel, Operator: blue, knob, 30mm, round, plastic, 120 VAC/VDC, full voltage.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/GCX1284-120L>

Technical Specifications

Brand	AutomationDirect
Item	Selector switch
Barrel Size	22mm
IP Rating	IP65
Number Of Positions	3
Action	Spring return to center
Bulb Type	LED illuminated
Contact Type	(2) N.O./ (2) N.C.
Base Material	Metal

Bezel Material	Metal
Operator Color	Blue
Operator Type	Knob
Operator Size	30mm
Operator Shape	Round
Operator Material	Plastic
Voltage Rating	120 VAC/VDC
Voltage Regulation	Full voltage

Agency Approvals

UL Listed File #	None
UL Recognized File #	E189258
UL Hazardous File #	None
CE	View CE declarations
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/GCX1284-120L.pdf>
See store item page for other formats.