


# GCX3244-24 Cut Sheet

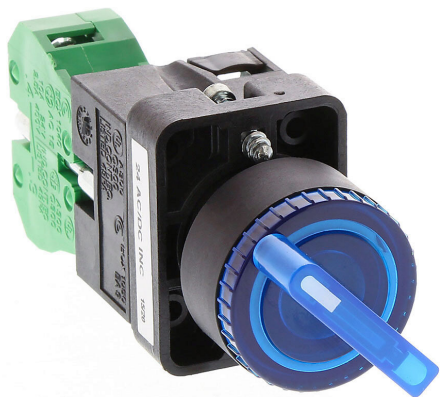

AutomationDirect selector switch, 22mm, 2-position, spring return from right, incandescent illuminated, (1) N.O. contact(s), plastic base, plastic bezel, Operator: blue, knob, 30mm, round, plastic, 24 VAC/VDC, full voltage.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/GCX3244-24>

## Technical Specifications

Brand	AutomationDirect
Item	Selector switch
Barrel Size	22mm
IP Rating	IP65
Number Of Positions	2
Action	Spring return from right
Bulb Type	Incandescent illuminated
Contact Type	(1) N.O.
Base Material	Plastic

Bezel Material	Plastic
Operator Color	Blue
Operator Type	Knob
Operator Size	30mm
Operator Shape	Round
Operator Material	Plastic
Voltage Rating	24 VAC/VDC
Voltage Regulation	Full voltage

## Agency Approvals

UL Listed File #	e189258
UL Recognized File #	None
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	66746
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/GCX3244-24.pdf>  
See store item page for other formats.