


GCX3263-120 Cut Sheet

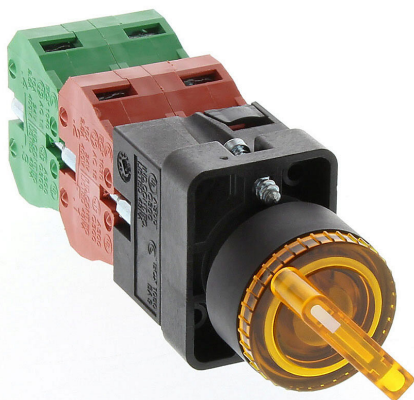

AutomationDirect selector switch, 22mm, 3-position, maintained, incandescent illuminated, (2) N.O./(2) N.C. contact(s), plastic base, plastic bezel, Operator: yellow, knob, 30mm, round, plastic, 120 VAC/VDC, full voltage.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/GCX3263-120>

Technical Specifications

Brand	AutomationDirect
Item	Selector switch
Barrel Size	22mm
IP Rating	IP65
Number Of Positions	3
Action	Maintained
Bulb Type	Incandescent illuminated
Contact Type	(2) N.O./(2) N.C.
Base Material	Plastic

Bezel Material	Plastic
Operator Color	Yellow
Operator Type	Knob
Operator Size	30mm
Operator Shape	Round
Operator Material	Plastic
Voltage Rating	120 VAC/VDC
Voltage Regulation	Full voltage

Agency Approvals

UL Listed File #	e189258
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	66746
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/GCX3263-120.pdf>
See store item page for other formats.