


GCX3264-120 Cut Sheet

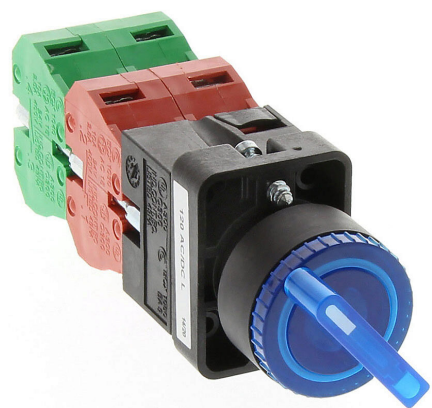

AutomationDirect selector switch, 22mm, 3-position, maintained, incandescent illuminated, (2) N.O./(2) N.C. contact(s), plastic base, plastic bezel, Operator: blue, knob, 30mm, round, plastic, 120 VAC/VDC, full voltage.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/GCX3264-120>

Technical Specifications

| | |
|---------------------|--------------------------|
| Brand | AutomationDirect |
| Item | Selector switch |
| Barrel Size | 22mm |
| IP Rating | IP65 |
| Number Of Positions | 3 |
| Action | Maintained |
| Bulb Type | Incandescent illuminated |
| Contact Type | (2) N.O./(2) N.C. |
| Base Material | Plastic |

| | |
|--------------------|--------------|
| Bezel Material | Plastic |
| Operator Color | Blue |
| Operator Type | Knob |
| Operator Size | 30mm |
| Operator Shape | Round |
| Operator Material | Plastic |
| Voltage Rating | 120 VAC/VDC |
| Voltage Regulation | Full voltage |

Agency Approvals

| | |
|----------------------|--|
| UL Listed File # | e189258 |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | View CE declarations |
| CSA File # | 66746 |
| RoHS Status | Yes (See CE Doc) |
| EU REACH | View EU REACH document |

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/GCX3264-120.pdf>
See store item page for other formats.