


# GMCBU-SH110-380VAC Cut Sheet

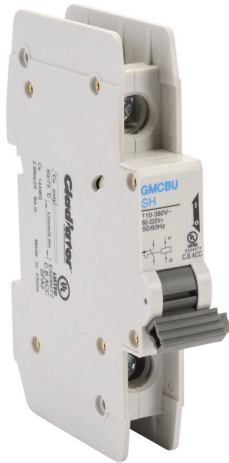

Gladiator shunt trip, left side mount, 110-380 VAC coil voltage.  
For use with Gladiator GMCBU series miniature circuit breakers.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/GMCBU-SH110-380VAC>

## Technical Specifications

<b>Brand</b>	Gladiator
<b>Item</b>	Shunt trip
<b>Mounting</b>	Left side
<b>Coil Voltage</b>	110-380 VAC
<b>For Use With</b>	Gladiator GMCBU series miniature circuit breakers

## Agency Approvals

<b>UL Listed File #</b>	E509077
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	None
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>